

CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

more than you expect




ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-3 @20°C	5.87 ohms max.
INDUCTANCE	1-3 100kHz, 100mVAC, Ls	2.0mH min.
DIELECTRIC	8-1 625VAC, 1 second	500VAC, 1 minute
⑥C TURNS RATIO	(1-3):(8-7)	100:1

GENERAL SPECIFICATIONS:
CURRENT RATING: 10A max.

⑥B UL recognized class B insulation system M1-130(B), E106391.

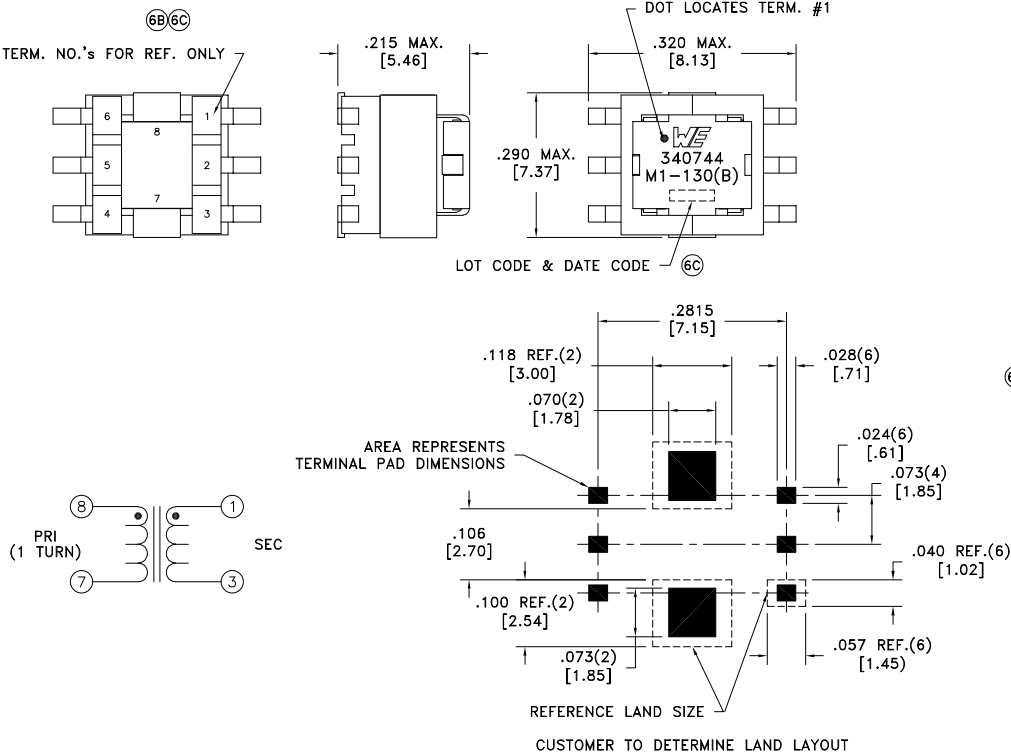

Wire insulation & RoHS status not affected by wire color.
Wire insulation color may vary depending on availability.

DETAILS SUBJECT TO CHANGE

REV.	DATE	Packaging Specifications	 CONVENTION PLACEMENT	Tolerances unless otherwise specified: Angles: $\pm 1^\circ$ Decimals: $\pm .005$ [.13] Fractions: $\pm 1/64$ Footprint: $\pm .005$ [.13]	DRAWING TITLE	PART NO.
		Method: Tape & Reel PKG-0215		This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	TRANSFORMER	750340744
6C	6/23	www.we-online.com/midcom				
6B	3/18					
6A	11/12	SEE REVISION SHEET FOR REVISION LEVEL		eiSos p/n: 750340744	 compliant RoHS	SPECIFICATION SHEET 1 OF 1