


CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

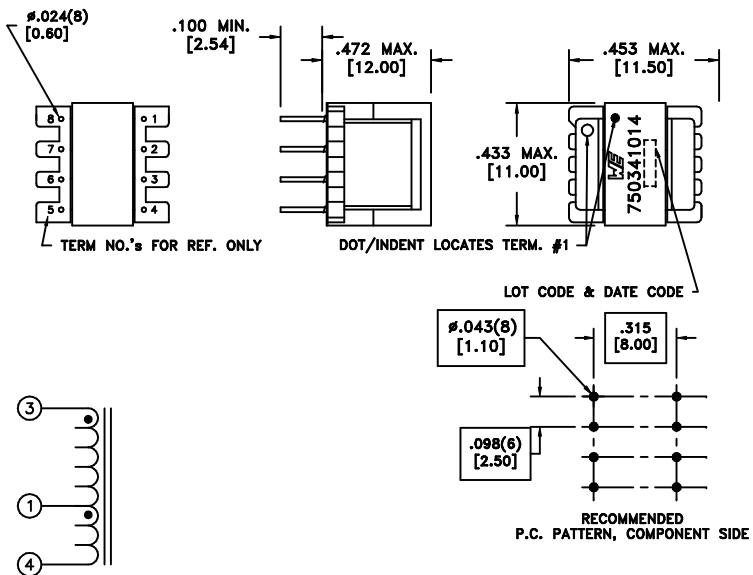


**ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:**

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	3-4 @20°C	1.20 ohms max.
D.C. RESISTANCE	3-1 @20°C	0.70 ohms max.
INDUCTANCE	3-1 10kHz, 10mVAC, Ls	340uH ±5%
SATURATION CURRENT		
DIELECTRIC		
URNS RATIO	(3-1):(1-4)	2.278:1, ±2%

**GENERAL SPECIFICATIONS:**

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

REV.	DATE	Packaging Specifications Method: <b>Tape &amp; Reel</b> PKG-0328 www.midcom-inc.com	 CONVENTION PLACEMENT	Tolerances unless otherwise specified: Angles: ±1° Fractions: ±1/64 Decimals: ±.005 [.13] Footprint: ±.005 [.13]	DRAWING TITLE <b>INDUCTOR</b>	PART NO. <b>750341014</b>
00	02/11	SEE REVISION SHEET FOR REVISION LEVEL		This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: <b>750341014</b>	SPECIFICATION SHEET 1 OF 1