



CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

more than you expect


 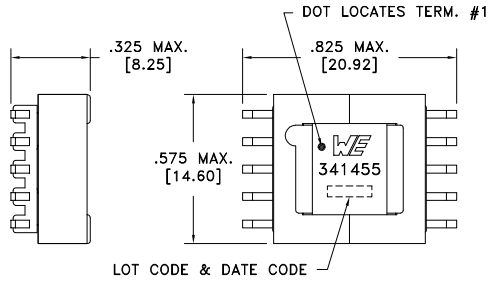


TERM. NO.'s FOR REF. ONLY

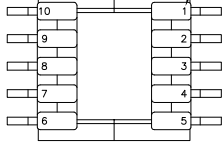

ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	2-5 @20°C	0.273 ohms ±10%
D.C. RESISTANCE	5-6 @20°C	0.331 ohms ±10%
INDUCTANCE	2-6 10kHz, 100mVAC, Ls	0.300mH ±10%
TURNS RATIO	(2-5):(5-6)	1:1, ±2%

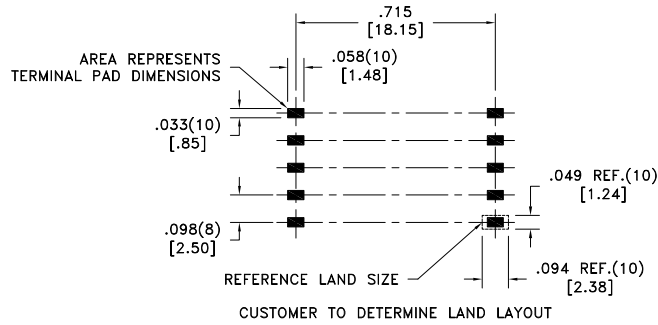

Wire insulation & RoHS status not affected by wire color.  
Wire insulation color may vary depending on availability.

REV.	DATE	Packaging Specifications Method: <b>Tape &amp; Reel</b> PKG-0920 www.we-online.com/midcom		Tolerances unless otherwise specified: Angles: ±1° Fractions: ±1/64 Decimals: ±.005 [.13] Footprint: ±.005 [.13]	DRAWING TITLE <b>INDUCTOR</b>	PART NO. <b>750341455</b>
6A	3/13	SEE REVISION SHEET FOR REVISION LEVEL		This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: 750341455	SPECIFICATION SHEET 1 OF 1