


CONNECTORS

REDFIT IDC SKEDD

WR-WST

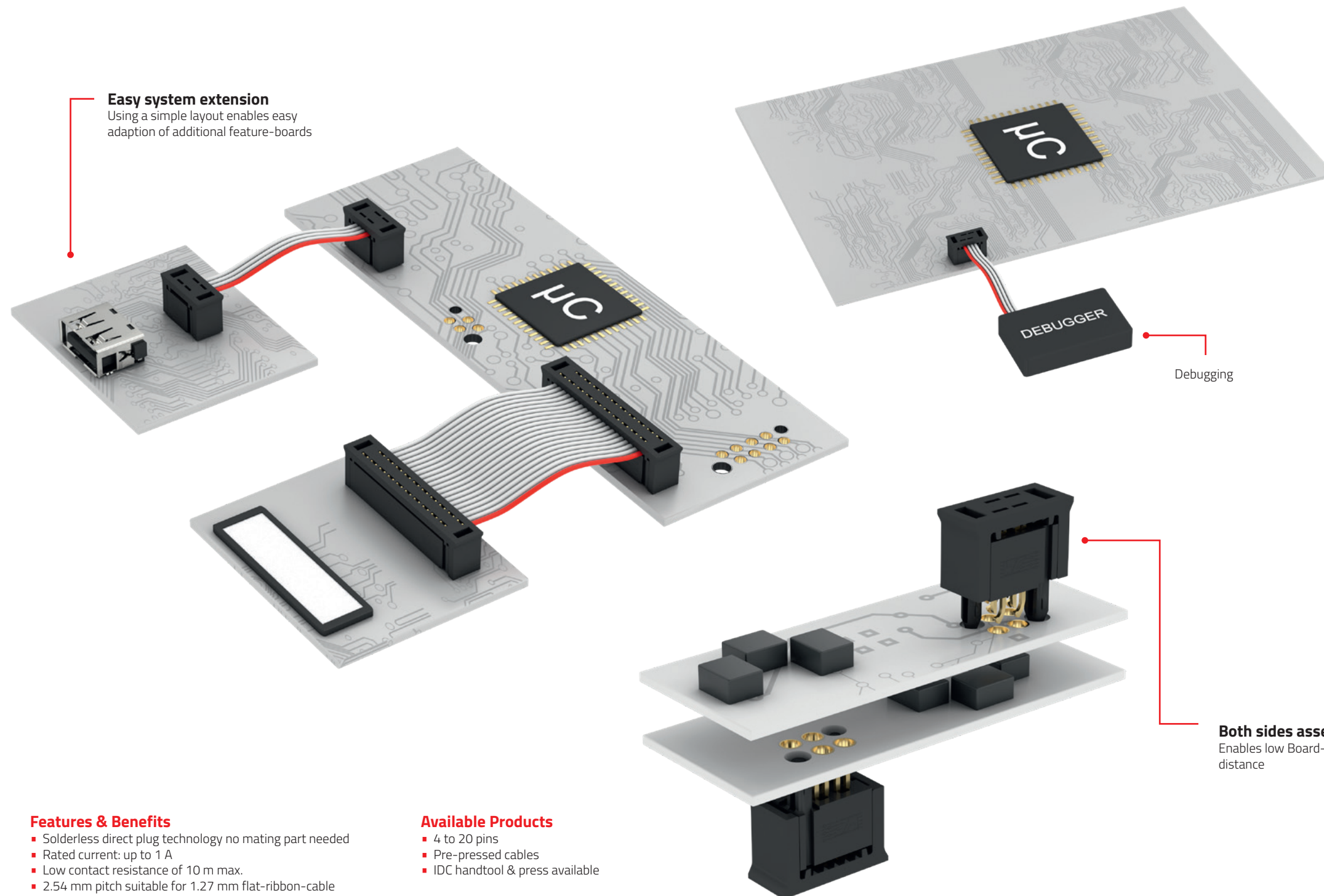

Easy system extension

Using a simple layout enables easy adaption of additional feature-boards


Features & Benefits

- Solderless direct plug technology no mating part needed
- Rated current: up to 1 A
- Low contact resistance of 10 m max.
- 2.54 mm pitch suitable for 1.27 mm flat-ribbon-cable
- UL94 V-0 material
- Working temperature: -25 °C to +105 °C
- Vibration resistant up to 10 g

Available Products

- 4 to 20 pins
- Pre-pressed cables
- IDC handtool & press available

Special Features

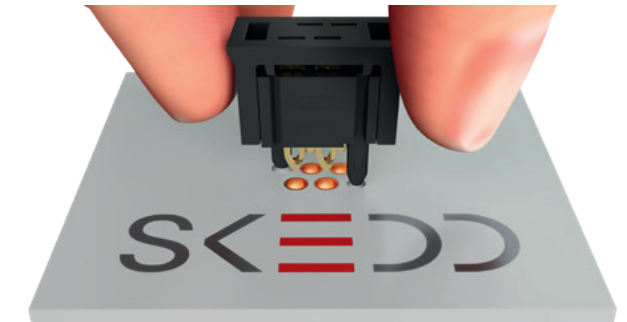

Easy assembling by hand

Debugging



No thermal process



Vibration resistant

Both sides assembly

Enables low Board-to-Board distance



Visit our online catalogue for detailed product selection:
www.we-online.com/REDFIT-IDC