

# CONNECTORS

## MICRO POWER CONNECTOR 3.0 MM

WR-MPC3




### Features & Benefits

- 3.00 mm pitch
- Current rating up to 5 A
- Working voltage up to 250 VAC
- Wire-to-Wire possible
- Coded system to prevent mismatching
- Highly secure positive locking system

### Available Products

- PCB and cable connectors
- 1 or 2 rows
- Vertical & horizontal
- PCB fixations: snap-in pegs, mounting flanges, solder tabs, metal retention clips
- Polarity from 2 to 24
- THT, SMT and Crimp types (AWG30 to AWG20)
- Low force contacts available
- Panel mount ears

### Variant Examples

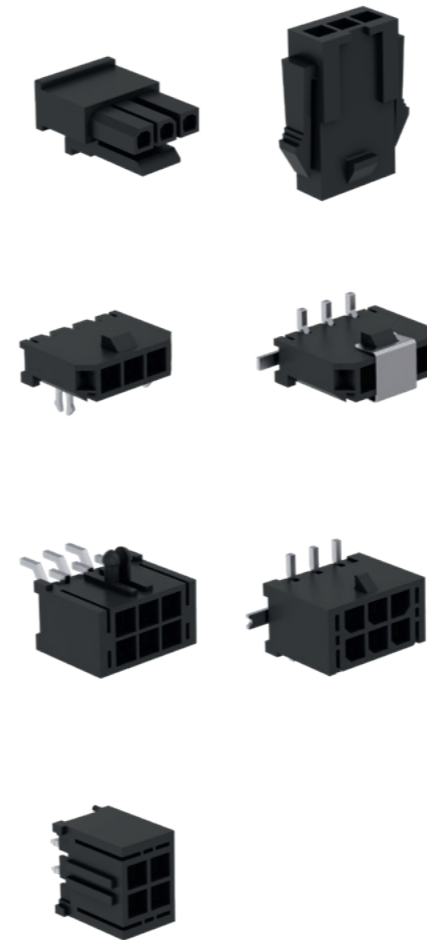


### Special Features



#### Low Force Crimp Contact available!

Reduces insertion and disconnecting force especially for higher polarity.

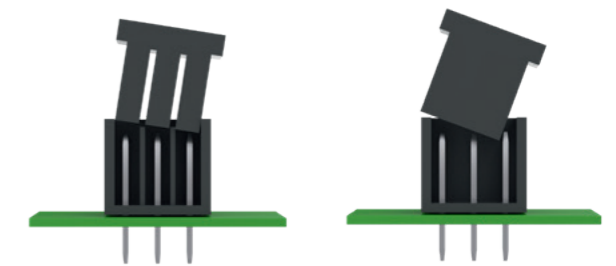

Scoop proof design

### Accessories / Tooling



Pre-crimped cable, handtool and applicator for semi-automatic tools

