



Connectors

Terminal Blocks – Pluggable Types


WR-TBL

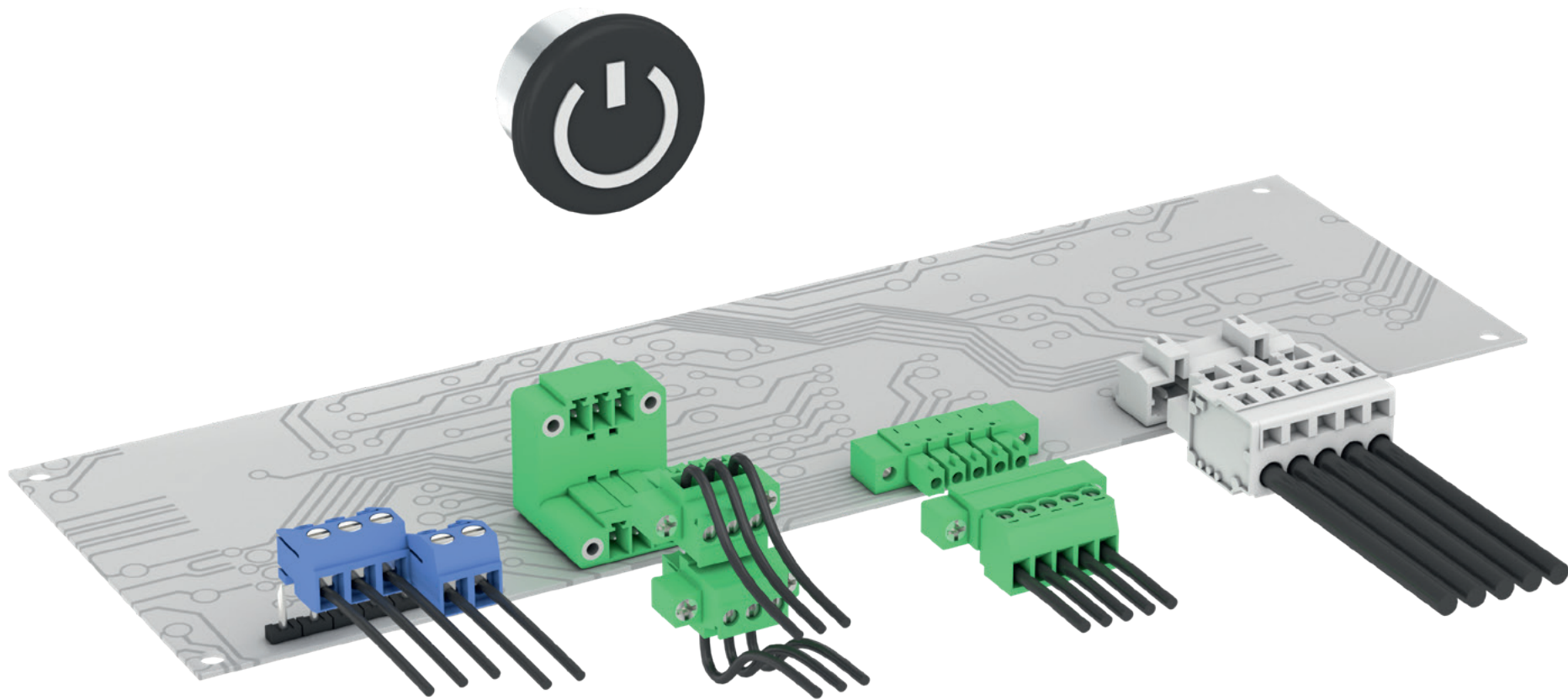

Types of Connection

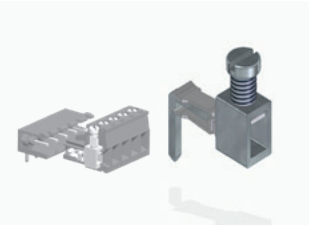


- Pluggable**
- Every monoblock connection technologies available
 - Reversed gender
 - Coding option

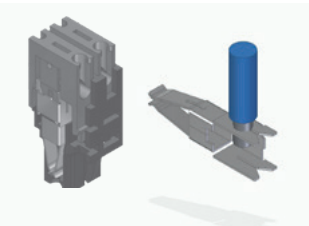

- IDC Clamp**
- Fast connection
 - No cable stripping

Accessories

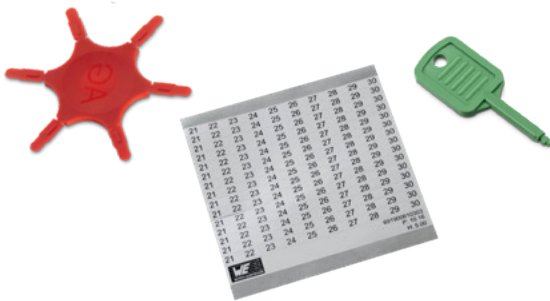

Coding keys, adhesive markers and removal key for dedicated series

Features & Benefits

- Current rating up to 20 A
- Working voltage up to 750 V_{AC}
- UL, cULus, VDE rated products
- Fast connection

Available Products

- 2 up to 24 pins
- THT & THR
- Double level versions
- Reversed gender available (Wire-to-Board and Wire-to-Wire connections possible)
- Pitches: 2.50 mm up to 7.62 mm
- Straight & right angled
- Open & closed sockets



Visit our online catalogue for detailed product selection:

www.we-online.com/TBL-PLUGGABLE