


# CONNECTORS

## TERMINAL BLOCKS – PLUGGABLE TYPES

WR-TBL

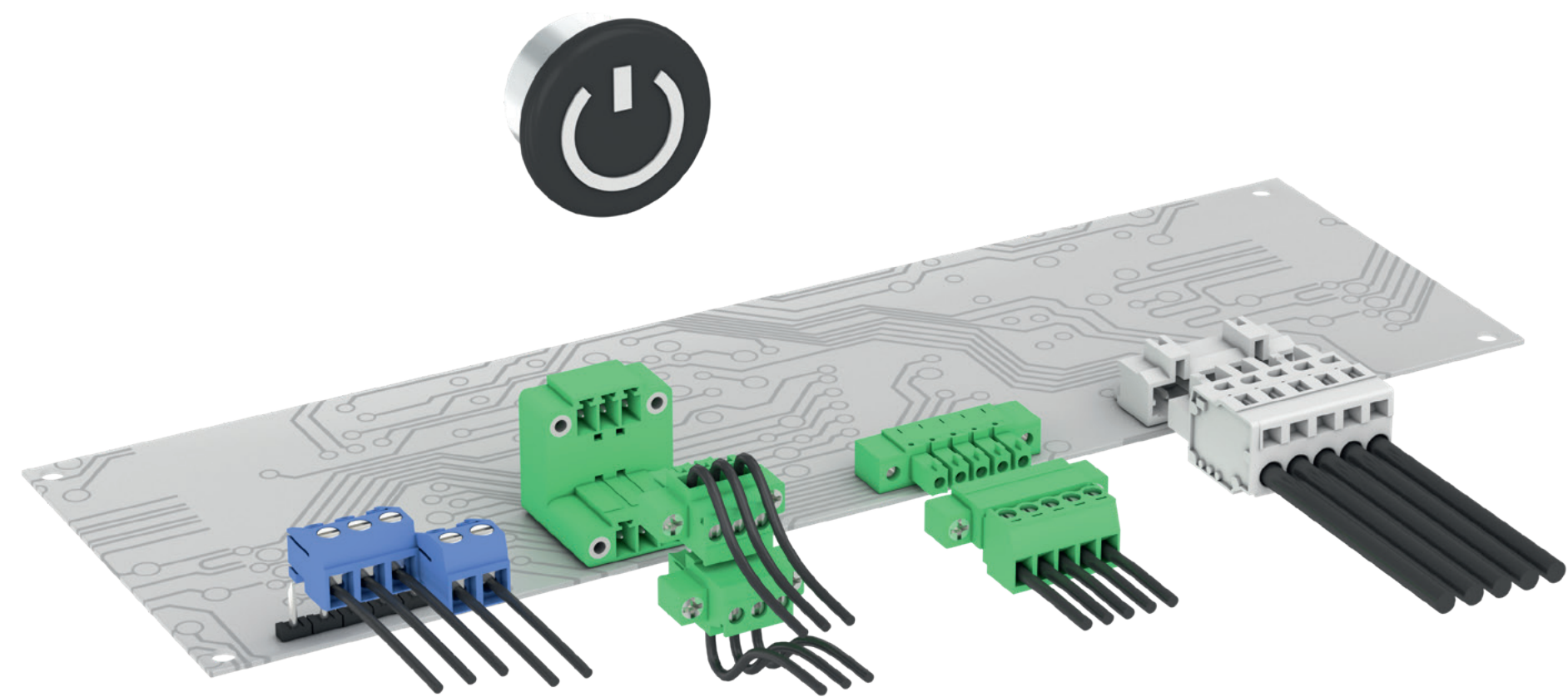


### Features & Benefits

- Current rating up to 20 A
- Working voltage up to 750 V<sub>AC</sub>
- UL, cULus, VDE rated products
- Fast connection

### Available Products


- 2 up to 24 pins
- THT & THR
- Double level versions
- Reversed gender available (Wire-to-Board and Wire-to-Wire connections possible)
- Pitches: 2.50 mm up to 7.62 mm
- Horizontal & vertical cable entry
- Open and closed PCB header

### Types of Connection

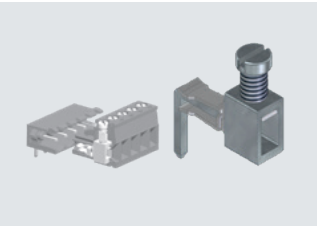

#### Pluggable


- Every monoblock connection technologies available
- Reversed gender
- Coding option

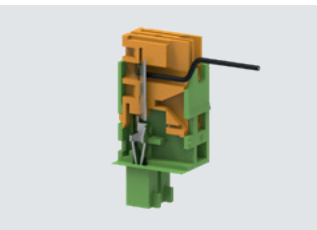

#### IDC Clamp

- Fast connection
- No cable stripping

### Accessories

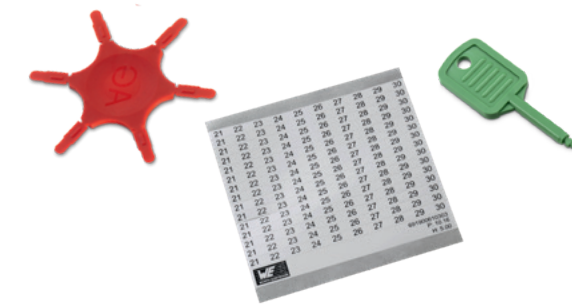

Coding keys, adhesive markers and removal key for dedicated series



Visit our online catalogue for detailed product selection:  
[www.we-online.com/TBL-PLUGGABLE](http://www.we-online.com/TBL-PLUGGABLE)