


CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

more than you expect

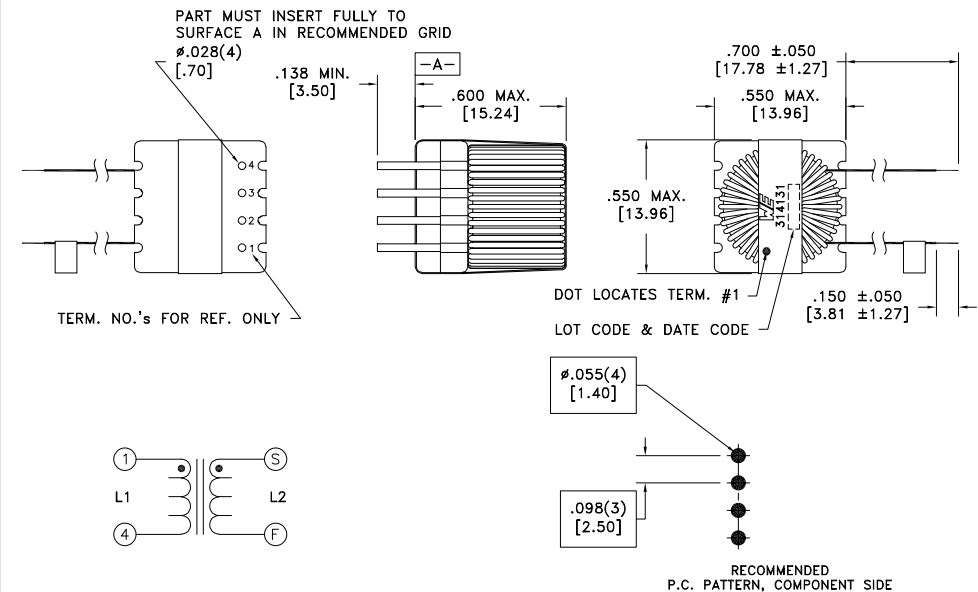

ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-4	@20°C
D.C. RESISTANCE	S-F	@20°C
INDUCTANCE	1-4	10kHz, 300mVAC, Ls
INDUCTANCE	S-F	10kHz, 300mVAC, Ls
DIELECTRIC	1-S	3750VAC, 1 second
URNS RATIO	(1-4):(S-F)	1:1, ±1%

GENERAL SPECIFICATIONS:
Safety Standard Undefined.

Wire insulation & RoHS status not affected by wire color.
Wire insulation color may vary depending on availability.

DETAILS SUBJECT TO CHANGE

REV.	DATE	Packaging Specifications		Tolerances unless otherwise specified: Angles: ±1° Fractions: ±1/64 Decimals: ±.005 Footprint: ±.001	DRAWING TITLE TRANSFORMER	PART NO. 750314131
6C	3/21	Method: Tray PKG-0101 www.we-online.com/midcom				
6B	3/19	SEE REVISION SHEET FOR REVISION LEVEL	CONVENTION PLACEMENT	This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: 750314131	SPECIFICATION SHEET 1 OF 1
6A	12/14					