


CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

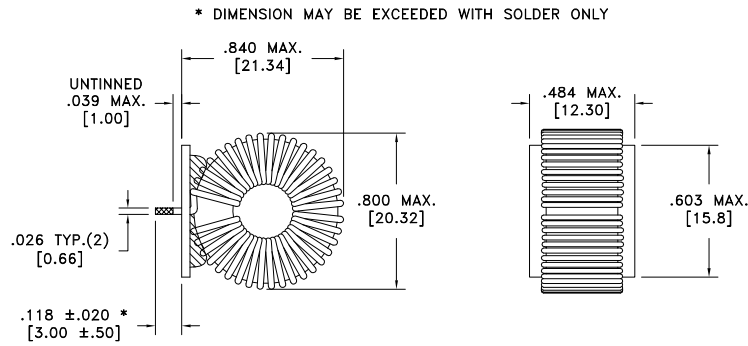


ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-2 @20°C	0.130 ohms max.
INDUCTANCE	1-2 40kHz, 1.0VAC, Ls	360uH ±15%
INDUCTANCE	1-2 40kHz, 1.0VAC, 2.5A, Ls	180uH typ.
DIELECTRIC	1-Core 1200VAC, 1 second	1000VAC, 1 minute

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C, including temp. rise.

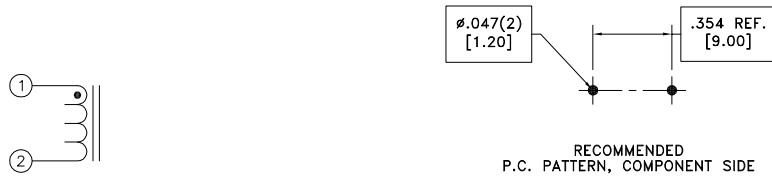

Wire insulation & RoHS status not affected by wire color.
Wire insulation color may vary depending on availability.

REV.	DATE	Packaging Specifications Method: Tray PKG-0784 www.we-online.com/midcom		Tolerances unless otherwise specified: Angles: ±1° Fractions: ±1/64 Decimals: ±.005 [.13] Footprint: ±.001 [.03]	DRAWING TITLE INDUCTOR DIFFERENTIAL CHOKE	PART NO. 750315755
6B	3/19			This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: 750315755	
6A	1/17	SEE REVISION SHEET FOR REVISION LEVEL				SPECIFICATION SHEET 1 OF 1