

CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes




ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-6 @20°C	0.019 ohms ±20%
INDUCTANCE	1-6 10kHz, 100mVAC, Ls	17.0uH ±10%
SATURATION CURRENT	1-6 20% rolloff from initial	20A

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

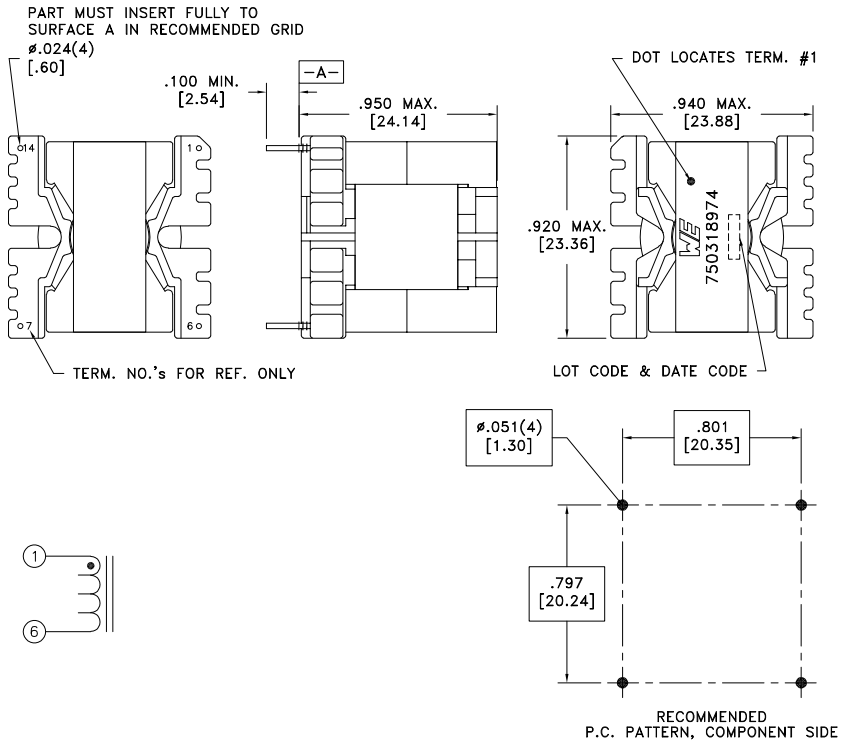

Wire insulation & RoHS status not affected by wire color.
 Wire insulation color may vary depending on availability.

REV.	DATE	Packaging Specifications Method: Tray PKG-0239 www.we-online.com/midcom	CONVENTION PLACEMENT
6A	4/23	SEE REVISION SHEET FOR REVISION LEVEL	

Tolerances unless otherwise specified:
 Angles: $\pm 1^\circ$
 Fractions: $\pm 1/64$
 Decimals: $\pm .005$ [.13]
 Footprint: $\pm .001$ [.03]

This drawing is dual dimensioned. Dimensions in brackets are in millimeters.

DRAWING TITLE
INDUCTOR

eiSos p/n: 750318974

PART NO.
750318974

SPECIFICATION SHEET 1 OF 1