

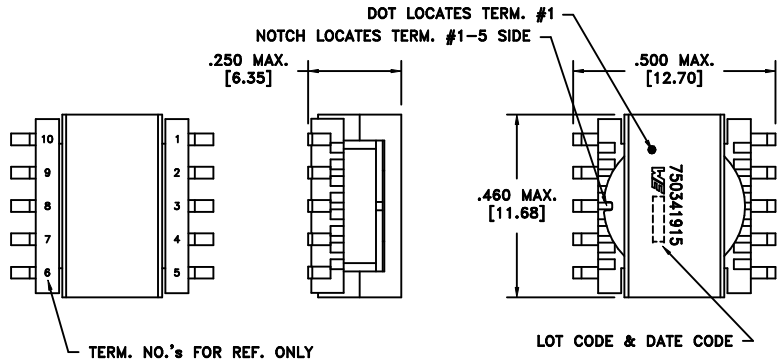


CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes

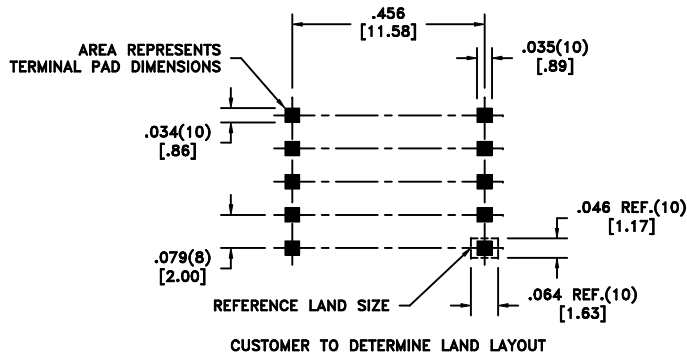

ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	1-2 @20°C	3.6 ohms MAX
D.C. RESISTANCE	7-4 @20°C	3.3 ohms MAX
INDUCTANCE	1-2 50kHz, 100mVAC, Ls	1.12mH±10%
TURNS RATIO	(1-2):(7-4)	1.946:1, ±2%
DIELECTRIC	2-4 500VAC, 1 second	-

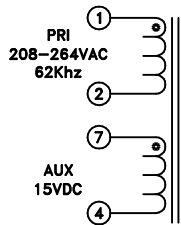

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

REFERENCE DESIGN

REV.	DATE	Packaging Specifications Method: Tape & Reel PKG-0121 www.we-online.com/midcom		Tolerances unless otherwise specified: Angles: ±1° Decimals: ±.005 [.13] Fractions: ±1/64 Footprint: ±.005 [.13]	DRAWING TITLE TRANSFORMER	PART NO. 750341915
01	6/13	SEE REVISION SHEET FOR REVISION LEVEL	CONVENTION PLACEMENT	This drawing is dual dimensioned. Dimensions in brackets are in millimeters.	eiSos p/n: 750341915	SPECIFICATION SHEET 1 OF 1
00	5/13					