

CUSTOMER TERMINAL	RoHS	LEAD(Pb)-FREE
Sn96%, Ag4%	Yes	Yes





ELECTRICAL SPECIFICATIONS @ 25°C unless otherwise noted:

PARAMETER	TEST CONDITIONS	VALUE
D.C. RESISTANCE	3-7 @20°C	0.380 ohms max.
D.C. RESISTANCE	9-11 @20°C	0.160 ohms max.
INDUCTANCE	3-7 100kHz, 100mVAC, Ls	760.00uH ±10%
DIELECTRIC	3-11 1250VAC, 1 second	-
TURNS RATIO	(3-7):(9-11)	10.42:1, ±2%

GENERAL SPECIFICATIONS:

OPERATING TEMPERATURE RANGE: -40°C to +125°C including temp rise.

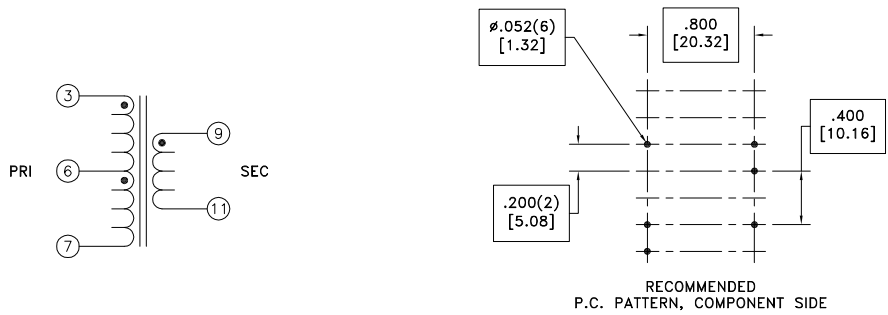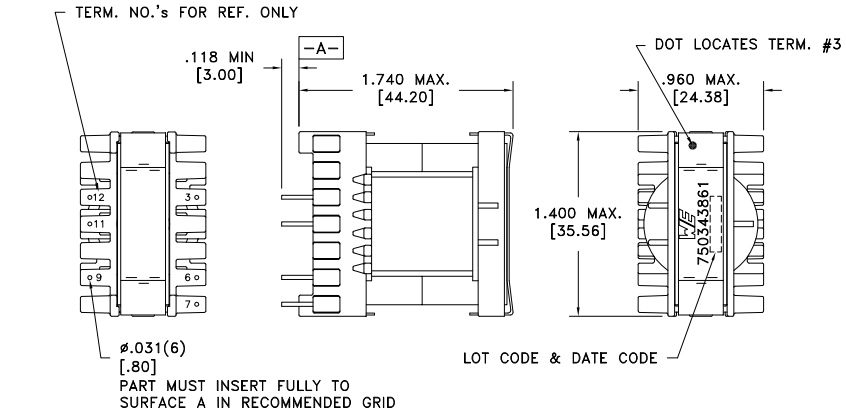

Wire insulation & RoHS status not affected by wire color.  
Wire insulation color may vary depending on availability.

REV.	DATE	Packaging Specifications	CONVENTION PLACEMENT
		Method: Tray PKG-1033 www.we-online.com/midcom	
6A	9/18	SEE REVISION SHEET FOR REVISION LEVEL	

Tolerances unless otherwise specified:  
Angles: ±1°  
Fractions: ±1/64  
Decimals: ±.005 [.13]  
Footprint: ±.001 [.03]

This drawing is dual dimensioned. Dimensions in brackets are in millimeters.

DRAWING TITLE  
**INDUCTOR**

eiSos p/n: 750343861

PART NO.  
**750343861**

compliant RoHS

SPECIFICATION SHEET 1 OF 1