


UNSEALED SPLITTER C1

Standard version

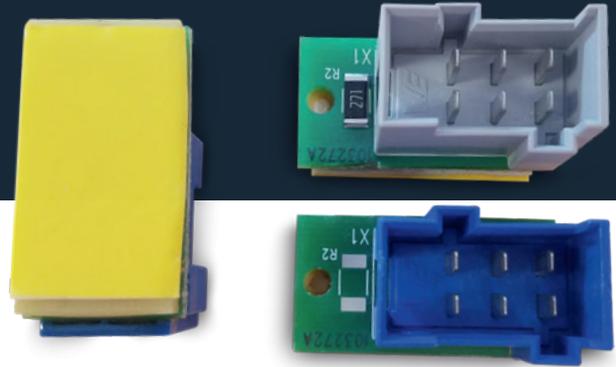

The **Unsealed Splitter C1** is a local star topology based junction for all electronics and control devices that are connected to a CAN bus.

The advantages of the Unsealed Splitter C1:

- Possibility to create a local CAN connection point for up to 3 CAN devices
- Easy installation and simplified wire harness architecture
- Available as standard with and without termination resistance


If you need a version with more connections, please contact us. We will develop an individual solution for you.

Technical Data	
Operating temperature	-40 °C to +85 °C
IP rating	IP00
Mounting point type	Ø 3.5 mm hole Double sided adhesive
Connector	JPT 6-pin
Dimensions	36.2 mm x 18.8 mm
Mating connectors (TE Part numbers)	no termination: 8-968970-1 with termination: 8-968970-2


Order information

Description	Part Number
Without Termination	ICS-103271
With Termination	ICS-103272

Mechanical information

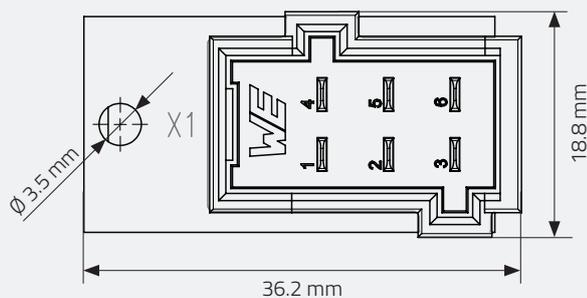

Electrical schematics

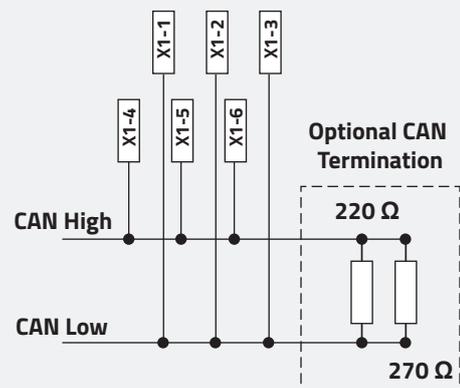

Technical content may be modified and changed by Würth Elektronik ICS GmbH & Co. KG without any notice.