

Connectors

Mini Module Connectors


WR-MM

Wire-to-Board solution

Board-to-Board solution

Wire-to-Board permanent solution

Special Features

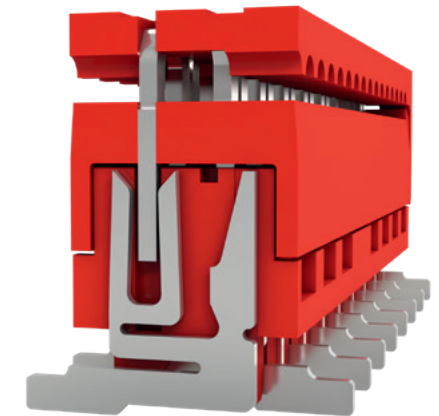

The special fork design of the female socket absorbs relative movements caused by vibration. This prevents fretting corrosion and avoids micro-cuts.



With vibration-absorbing system

Features & Benefits

- Compact and low profile connectors: more compact than standard box headers
- Tin-plated design: lead-free and RoHS compliant
- Pitch: 2.54 mm / Pseudo-pitch: 1.27 mm
- For 1.27 mm flat-ribbon cable (AWG28)
- Reliable solution for Wire-to-Board and Board-to-Board applications
- IDC tools for easy cable assembling available

Available Products

- 4 to 26 pins
- SMT, THT, IDC
- Straight & right angled
- With or without coding
- With or without locking feature (for Wire-to-Board)



Visit our online catalogue for detailed product selection:
www.we-online.com/MM-BTB



Visit our online catalogue for detailed product selection:
www.we-online.com/MM-WTB